


B 52004

AMTEC® screws

Button head | cross-slot pozidriv

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

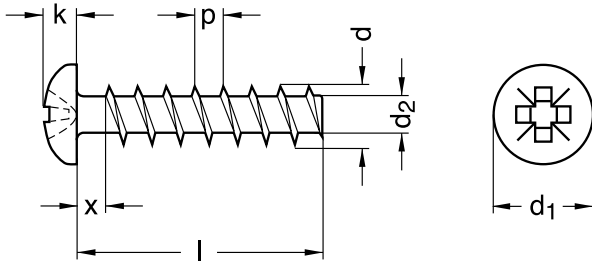

Diameter (d)	d ₁ nominal size	d ₂		k nominal size	Pitch (P)	x max.	Tool size
		min.	max.				
2.5	4.4	1.7	1.6	1.7	1.12	2.2	Z1
3	5.3	2.1	2.0	2.0	1.35	2.8	Z1
3.5	6.1	2.3	2.2	2.5	1.60	3.2	Z2
4	7	2.5	2.4	2.7	1.80	3.6	Z2
5	8.8	3.0	2.9	3.4	2.20	4.6	Z2
6	10.5	3.5	3.4	4.0	2.60	5.6	Z3

nominal size	Length (l)	
	min.	max.
6	5.40	6.60
8	7.25	8.75
10	9.25	10.75
12	11.10	12.90
16	15.10	16.90
20	18.95	21.05

nominal size	Length (l)	
	min.	max.
25	23.95	26.05
30	28.95	31.05

Diameter (d)	Length (l)							
	6	8	10	12	16	20	25	30
2.5	●	●						
3	●	●	●	●	●			
3.5		●	●	●	●	●		
4		●	●	●	●	●	●	
5					●	●		
6					●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

