


B 52006

AMTEC® screws

Flanged button head | hexalobular drive

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

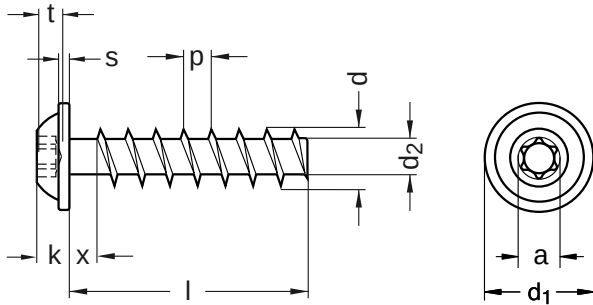

Diameter (d)	a max.	d ₁ nominal size	d ₂		k nominal size	s nominal size	Pitch (P)	t		x max.	Tool size
			nominal size	min. / max.				max.	min.		
2.5	2.40	5	1.6	1.5 / 1.7	1.5	0.5	1.12	1.0 / 0.75	2.2	T6	
3	2.80	6	2	1.9 / 2.1	2.1	0.6	1.35	1.3 / 1.00	2.8	T10	
3.5	2.80	7	2.2	2.1 / 2.3	2.4	0.7	1.60	1.4 / 1.10	3.2	T10	
4	3.95	8	2.4	2.3 / 2.5	2.6	0.8	1.80	1.7 / 1.25	3.6	T20	

nominal size	Length (l)	
	min.	max.
6	5.40	6.60
8	7.25	8.75
10	9.25	10.75
12	11.10	12.90
16	15.10	16.90
20	18.95	21.05

Diameter (d)	Length (l)					
	6	8	10	12	16	20
2.5	●	●	●			
3	●	●	●	●		
3.5		●	●	●		
4		●	●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

