


B 53060
Shaft locks

Spring steel | mechanically zinc-plated | Cr(VI)-free

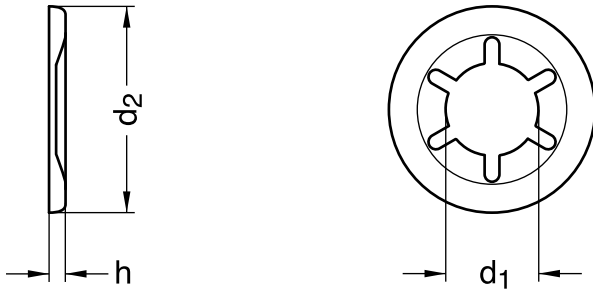

Diameter (d)	d ₁		nominal size	d ₂		nominal size	h		
	min.	max.		min.	max.		min.	max.	
3	2.50	2.81	9.7	9.4	10.0	1.3	1.1	1.5	
4	3.57	3.80	11.5	11.2	11.8	1.3	1.1	1.5	
5	4.51	4.74	11.5	11.2	11.8	1.3	1.1	1.5	
6	5.45	5.70	15.3	15.0	15.6	1.3	1.1	1.5	
8	7.40	7.66	15.3	15.0	15.6	1.3	1.1	1.5	
10	9.49	9.74	18.4	18.1	18.7	1.9	1.7	2.1	
12	11.37	11.62	25	24.7	25.3	2.3	2.1	2.5	

All technical data refer to the measure mm

