


DIN 125 A similar to ISO 7089/7090

Washers

Form A: without chamfer

Steel 140 HV | nickel plated | Cr(VI)-free

Further information: DIN standard has been withdrawn

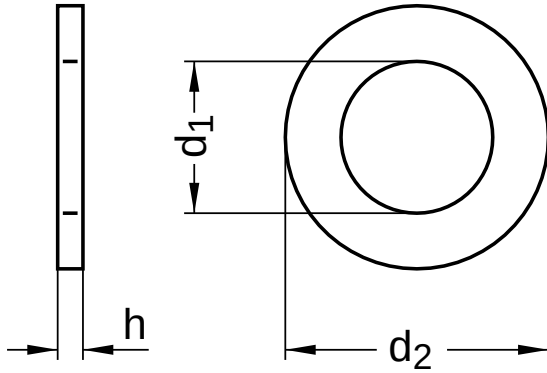

Diameter (d)	d ₁		d ₂		nominal size	h	
	min.	max.	min.	max.		min.	max.
2.2	2.2	2.34	4.70	5	0.3	0.25	0.35
3.2	3.2	3.38	6.64	7	0.5	0.45	0.55
3.7	3.7	3.88	7.64	8	0.5	0.45	0.55
4.3	4.3	4.48	8.64	9	0.8	0.70	0.90
5.3	5.3	5.48	9.64	10	1.0	0.90	1.10
6.4	6.4	6.62	11.57	12	1.6	1.40	1.80
10.5	10.5	10.77	19.48	20	2.0	1.80	2.20
13	13.0	13.27	23.48	24	2.5	2.30	2.70

All technical data refer to the measure mm

