


DIN 127 A
Spring washers

Form A: bent open

Stainless steel A4 | Cr(VI)-free

Further information: Norm has been withdrawn without replacement

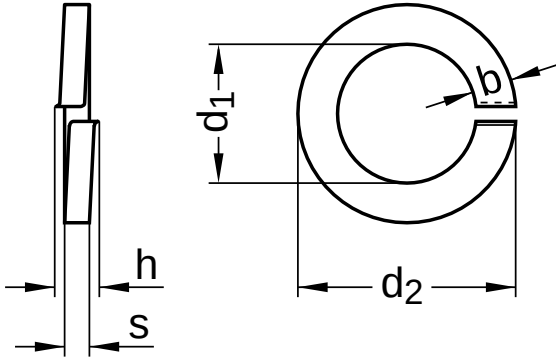

Diameter (d)	nominal size	b		d ₁		d ₂ max.	h		nominal size	s	
		min.	max.	min.	max.		min.	max.		min.	max.
4	1.5	1.40	1.60	4.1	4.4	7.6	2.1	2.5	0.9	0.80	1.00
10	3.5	3.30	3.70	10.2	10.7	18.1	5.0	5.9	2.2	2.05	2.35
12	4.0	3.80	4.20	12.2	12.7	21.1	5.8	6.8	2.5	2.35	2.65
24	7.0	6.75	7.25	24.5	25.5	40.0	11.0	13.0	5.0	4.80	5.20

All technical data refer to the measure mm

