


DIN 404
Capstan screws

Cylinder head | with slot

Steel 5.8 | bright | Cr(VI)-free | Metric thread

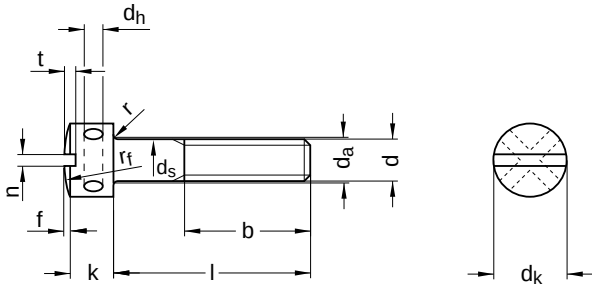

Diameter (d)	b nominal size	da max.	dh		dk		ds		f	nominal size	k	
			min.	max.	min.	max.	min.	max.			min.	max.
M3	19	3.6	1.5	1.64	5.38	5.5	2.86	3	0.5	4.0	3.62	4.38
M4	22	4.7	2.0	2.14	6.85	7.0	3.82	4	0.6	5.0	4.62	5.38
M5	25	5.7	2.5	2.64	8.35	8.5	4.82	5	0.7	6.5	6.05	6.95
M6	28	6.8	3.0	3.14	9.85	10.0	5.82	6	0.9	8.0	7.55	8.45

Diameter (d)	nominal size	n		rf	r min.	Pitch (P)	t	
		min.	max.				max.	min.
M3	0.8	0.86	1.00	8	0.10	0.5	1.25	1.0
M4	1.0	1.06	1.20	10	0.20	0.7	1.70	1.4
M5	1.2	1.26	1.51	16	0.20	0.8	2.00	1.7
M6	1.6	1.66	1.91	16	0.25	1.0	2.60	2.2

nominal size	Length (l)	
	min.	max.
5	4.8	5.2
6	5.8	6.2
8	7.7	8.3
10	9.7	10.3

nominal size	Length (l)	
	min.	max.
12	11.7	12.3
16	15.7	16.3
20	19.6	20.4

All technical data refer to the measure mm



DIN 404

Capstan screws

Cylinder head | with slot

Steel 5.8 | bright | Cr(VI)-free | Metric thread

Diameter (d)	Length (l)						
	5	6	8	10	12	16	20
M3	●	●	●	●			
M4	●	●	●	●	●	●	●
M5			●	●	●	●	●
M6						●	

- Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

