


DIN 976 A

Threaded rods

Form A: thread end without tip | length: 1 m

Stainless steel A4 | Cr(VI)-free | Metric thread

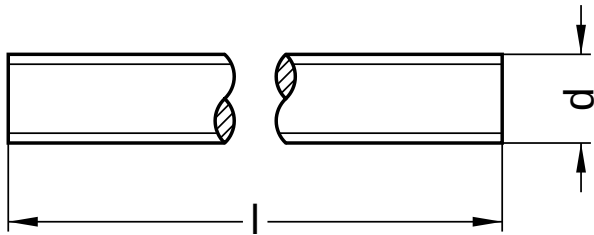

Diameter (d)	Pitch (P)	Length (l)		
		nominal size	min.	max.
M2	0.40	1,000	995.5	1,004.5
M2.5	0.45	1,000	995.5	1,004.5
M4	0.70	1,000	995.5	1,004.5
M5	0.80	1,000	995.5	1,004.5
M6	1.00	1,000	995.5	1,004.5
M8	1.25	1,000	995.5	1,004.5
M10	1.50	1,000	995.5	1,004.5
M12	1.75	1,000	995.5	1,004.5
M14	2.00	1,000	995.5	1,004.5
M16	2.00	1,000	995.5	1,004.5
M18	2.50	1,000	995.5	1,004.5
M20	2.50	1,000	995.5	1,004.5
M22	2.50	1,000	995.5	1,004.5
M24	3.00	1,000	995.5	1,004.5
M27	3.00	1,000	995.5	1,004.5
M30	3.50	1,000	995.5	1,004.5
M33	3.50	1,000	995.5	1,004.5
M36	4.00	1,000	995.5	1,004.5

All technical data refer to the measure mm

