


DIN 976 A

Threaded rods

Form A: thread end without tip | length: 1 m

Steel 4.8 | bright | Cr(VI)-free | Metric left-handed thread

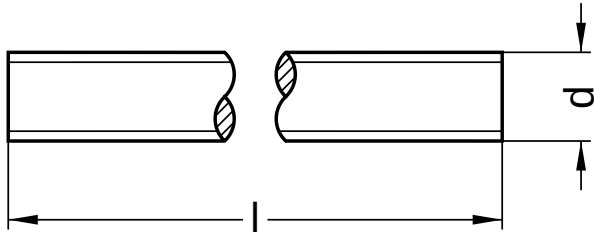

Diameter (d)	Pitch (P)	Length (l)		
		nominal size	min.	max.
M8	1.25	1,000	995.5	1,004.5
M10	1.50	1,000	995.5	1,004.5
M12	1.75	1,000	995.5	1,004.5
M14	2.00	1,000	995.5	1,004.5
M16	2.00	1,000	995.5	1,004.5
M18	2.50	1,000	995.5	1,004.5
M20	2.50	1,000	995.5	1,004.5
M24	3.00	1,000	995.5	1,004.5
M30	3.50	1,000	995.5	1,004.5

All technical data refer to the measure mm

