

# RIVQUICK® Varigrip multigrip blind rivets

## Large head

Note: aluminium body and steel mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d <sub>1</sub> nominal size	d <sub>2</sub> nominal size	Drilling diameter d nominal size	e	
					min.	max.
4.8	22021648169	4.8	16.5	4.9	6.4	12.7
	22021648248		16.5	4.9	12.7	19.8
	22121648100		16	5.0 - 5.2	1.0	6.0

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
4.8	16.9	2.5	1320	2000
	24.8	2.5	1320	2000
	10.0	2.0	1700	2200

All technical data refer to the measure mm



### Symbol list

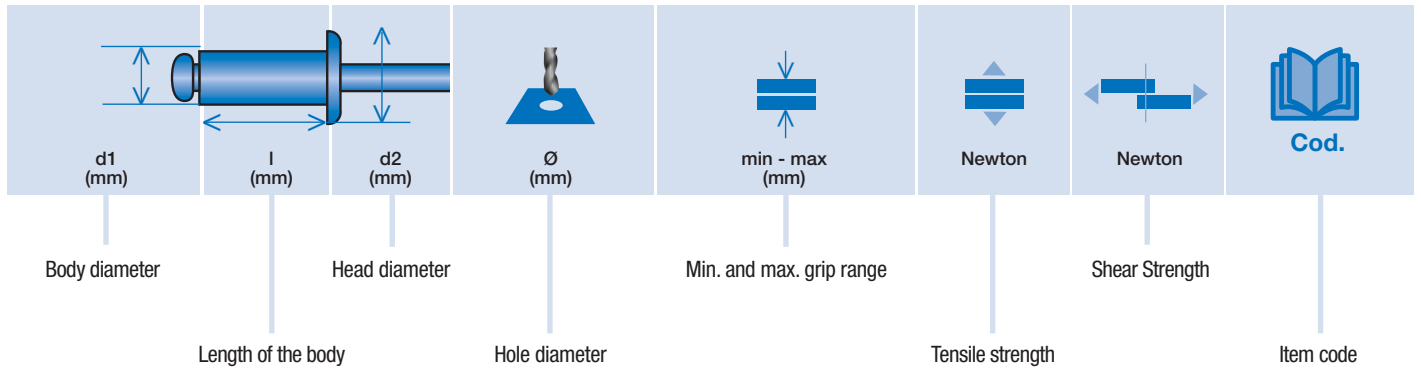

All technical data refer to the measure mm

