


SNAPLOC® Coupling

Without collar for mounting dome

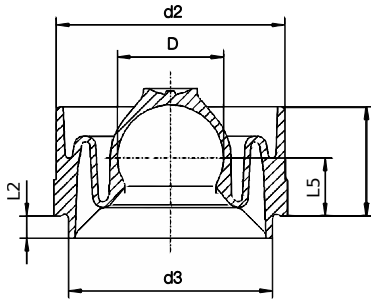

Article number	d ₂ nominal size	Depth (L1)	Colour	Ball diameter (D)	d ₃ nominal size	Hardness	L ₃	L5	Material thickness (L2)
40410803018	18	7.9	black	8	14	78 Shore A	10	4.9	3
40411003024	24	9.0	black	10	22	78 Shore A	12	6	3
40411013024	24	9.0	black	10	22	86 Shore A	12	6	3
40411503032	32	11.0	black	15	28	78 Shore A	15	8	3
40411523032	32	11.0	black	15	28	59 Shore A	15	8	3

All technical data refer to the measure mm

